

## SHEET METAL FORMER



## THE 2 IN 1 HAMMER



**HALDER**



german  
brand  
award  
'19  
gold



### SIMPLEX SERIES 3117

- Perfect for working on delicate workpieces
- Extremely lightweight aluminium housing
- All parts are replaceable
- High quality wood handle
- 2 different inserts: TPE-soft (blue, soft, **non-marring**) / Superplastic (white, medium hard, very durable, wear-resistant)

Art. No.	∅ [in]	[oz]	[in]
3117.030	1.18	6.53	12
3117.040	1.57	12.35	13



### FERROPLEX SERIES 3677

- Industrial/mechanics hammer and soft-face mallet in one
- With steel tube handle and ergonomic rubber grip
- Hammer head made of heat-treated steel
- Opposite side with exchangeable nylon insert, **no chipping** (even at temperatures below zero)

Art. No.	∅ [mm]	[oz]	[mm]
3677.030	1.18	21.16	11.42
3677.035	1.38	28.22	11.61

### MAGNETIC HOLDER



- Tremendous holding force thanks to neodymium magnets
- Ideal for holding vapour barrier to steel surfaces
- Easily hang compressed air hoses, tape rolls, cables and clothing
- Rubber-encased magnet prevents scratches and is resistant to oil

Art. No.	Color	∅ [in]	[oz]
3688.002	blue	2.95	8.82
3688.003	black	2.95	8.82


**HALDER**  
USA

**HALDER, INC.**

821 W College Ave  
Waukesha, WI 53186

www.halderusa.com  
sales@halderusa.com  
(888) 395-0168

Distributed by:

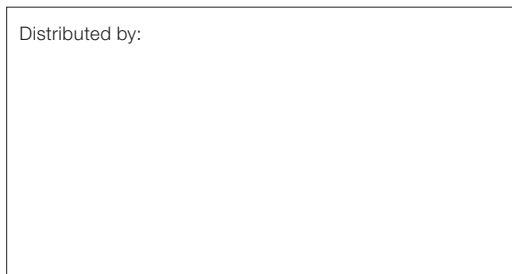

103.116

GB/USA/05/2020



**THE ORIGINAL FOR PROFESSIONALS**

**CARPENTRY / SHEET METAL FORMING**

# WOOD WORKING



# WOOD WORKING NON-REBOUND



# PLUMBER / SHEET METAL WORK



## SIMPLEX SERIES 3027

- All parts are replaceable
- High quality wood handle
- Robust and extremely durable cast iron housing
- 2 different inserts: Rubber composition (black, medium hard, impact cushioning, odorless, low-wear hardness) / Superplastic (white, medium hard, very durable, wear-resistant)

Art. No.	∅ [in]	[oz]	[in]
3027.060	2.36	53.26	15.94
3027.080	3.15	97.71	19.29

## SLEDGE HAMMER SIMPLEX SERIES 3027.VS

- All parts are replaceable
- High quality Hickory handle, high density, long-stranded, very robust
- Robust and extremely durable cast iron housing
- 2 different inserts: Rubber composition (black, medium hard, impact cushioning, odorless, low-wear hardness) / Superplastic (white, medium hard, very durable, wear-resistant)

Art. No.	∅ [in]	[oz]	[in]
3027.081	3.15	111.82	31.50
3027.100	3.94	188.72	39.37

## SECURAL MODEL 3380

- **Maximum rebound damping**
- Absolutely unbreakable connection
- Interchangeable inserts made of polyurethane: rectangular, noise-dampening, impact cushioning, wear-resistant

Art. No.	∅ [in]	[oz]	[in]
3380.040	1.18x1.57	23.99	12
3380.045	1.37x1.77	35.28	12.20

## SUPERCRAFT SERIES 3366

- **Non-rebound, high impact**
- Safe alternative to hitting steel on steel
- Vibration-reducing Hickory handle
- Replaceable inserts made of hard extruded nylon: **No chipping** (even at temperatures below zero), will not crack

Art. No.	∅ [in]	[oz]	[in]
3366.020	0.79	8.64	11.81
3366.025	0.98	11.46	12.01
3366.030	1.18	16.23	12.99
3366.035	1.38	19.75	13.19
3366.040	1.57	25.22	13.98

## SUPERCRAFT SERIES 3377

- **Non-rebound, high impact**
- Break-proof steel tube handle and ergonomic, anti-slip grip
- Replaceable inserts made of hard extruded nylon: **No chipping** (even at temperatures below zero), will not crack

Art. No.	∅ [in]	[oz]	[in]
3377.050	1.97	40.57	12.40
3377.060	2.36	61.73	12.80
3377.070	2.76	79.37	13.19

## BASEPLEX SERIES 3968

- High-quality zinc die cast base body with handle impact protection
- Wooden handle ergonomic, varnished
- Replaceable inserts: Cellulose acetate (red, hard, oil and grease resistant) / Nylon (white, hard, wear-resistant, **no chipping**)

Art. No.	∅ [in]	[oz]	[in]
3968.025	0.98	7.58	10.63
3968.030	1.18	12.70	11.02
3968.040	1.57	17.99	12.80