

Extension Nuts • (height 3 d)

EH 23090.



Product Description

In comparison to a hexagon nut according to DIN 6330, the extension nuts are elongated and are particularly suitable as a connecting piece for stud bolts.

Material


- Heat-treated steel, tempered, quality 10, phosphated

More information

References

For torques and strengths please refer to appendix - Technical Data -


Drawing

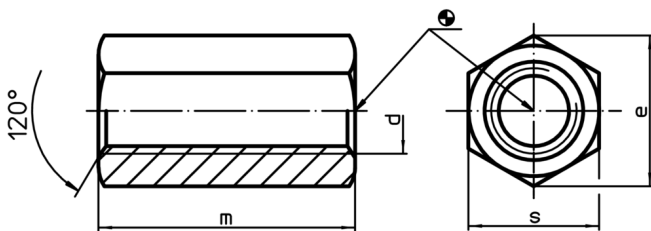

Order information

d	Dimensions			[g]	Art. No.
	e	m	s		
M 6	11.5	18	10	8.7	23090.0006
M 8	15.0	24	13	19.0	23090.0008
M10	18.5	30	16	35.0	23090.0010
M12	20.8	36	18	49.0	23090.0012
M14	24.2	42	21	79.0	23090.0014
M16	27.7	48	24	119.0	23090.0016
M20	34.6	60	30	228.0	23090.0020
M24	41.6	72	36	403.0	23090.0024
M30	53.1	90	46	819.0	23090.0030
M36	63.5	108	55	1386.0	23090.0036

Application example

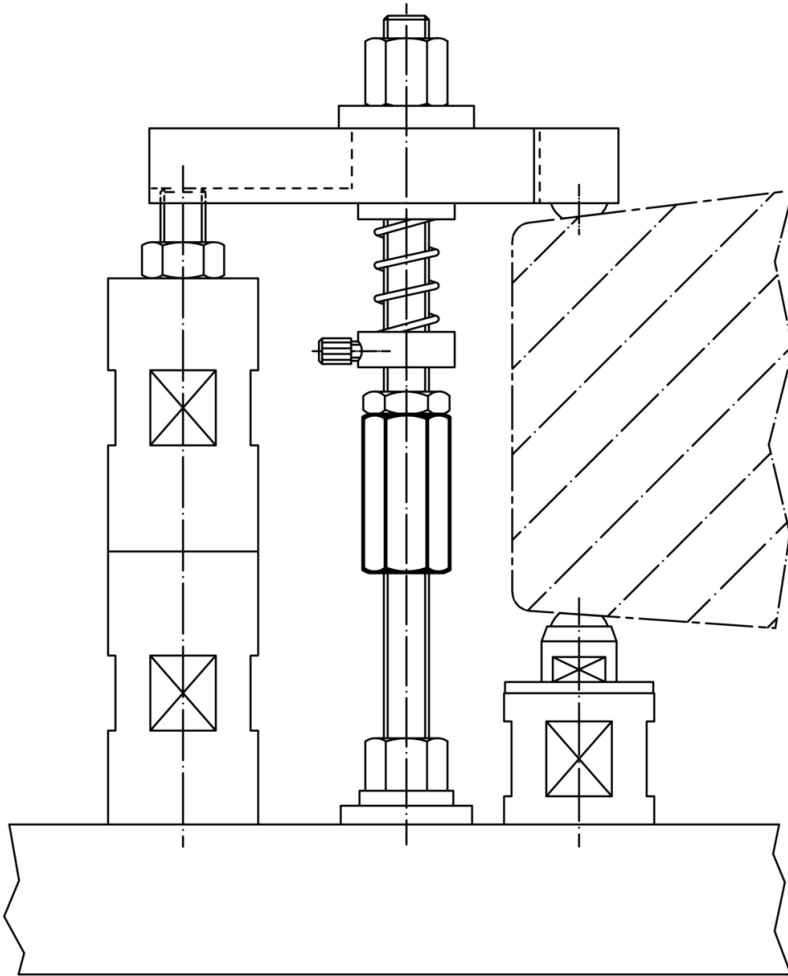

Compliance

RoHS compliant

Compliant according to Directive 2011/65/EU and Directive 2015/863

Does not contain SVHC substances

No SVHC substances with more than 0.1% w/w contained - SVHC list [REACH] as of 10.06.2022

Does not contain Proposition 65 substances

No Proposition 65 substances included
<https://www.P65Warnings.ca.gov/>

Free from Conflict Minerals

This product does not contain any substances designated as "conflict minerals" such as tantalum, tin, gold or tungsten from the Democratic Republic of Congo or adjacent countries.